



STADIUM LIGHT FIXTURES

PART NUMBERS:

GI-STL-30C1000-ETL4 | 30° BEAM | 300W | 48,000LM | 100 277V
GI-STL-30C1500-ETL4 | 30° BEAM | 500W | 80,000LM | 100 277V
GI-STL-15C3000-ETL4 | 15° BEAM | 1,00W | 120,000LM | 100 277V
GI-STL-30C4000-ETL4 | 30° BEAM | 1,200W | 192,000LM | 100 277V

5000K

ALL MODELS ARE 5000K

*MORE OPTIONS AVAILABLE IN 15° BEAM ANGLE AND 480V -
 REACH OUT FOR MORE INFORMATION OR VISIT US AT
WWW.GREENIGNITE.COM





SCAN THE QR CODE
 TO VIEW OUR FULL LINE
 OF STADIUM LIGHTS
 ON OUR WEBSITE

MORE FEATURES

- WATERPROOF
- 0-10V DIMMABLE
- 10-YEAR WARRANTY
- 20KV SURGE PROTECTION
- 0.193M² EPA RATING
- 50,000 HOUR LIFESPAN

OPTIONAL ACCESSORIES:

GI-ACC-STSB | LARGE TRUNNION BRACKET
GI-ACC-STST | SMALL TRUNNION BRACKET
GI-ACC-STAG | ANTI-GLARE COVER
GI-ACC-STCB | ROTATABLE BRACKET
GI-ACC-ST60 | 60FT CABLE

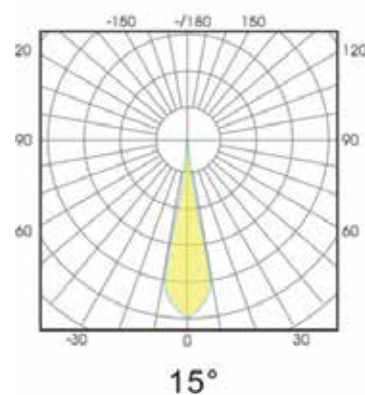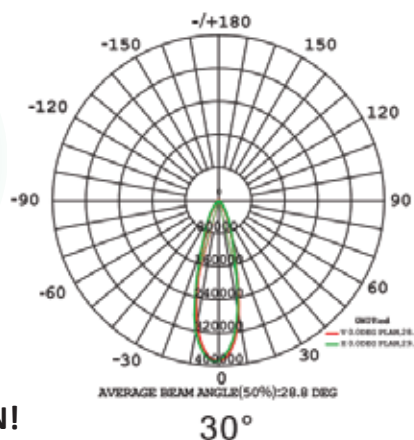

*CONTACT US FOR A LIGHTING SIMULATION!