


FieldLink[®] SPE cables (Single Pair Ethernet)

for industrial
communication

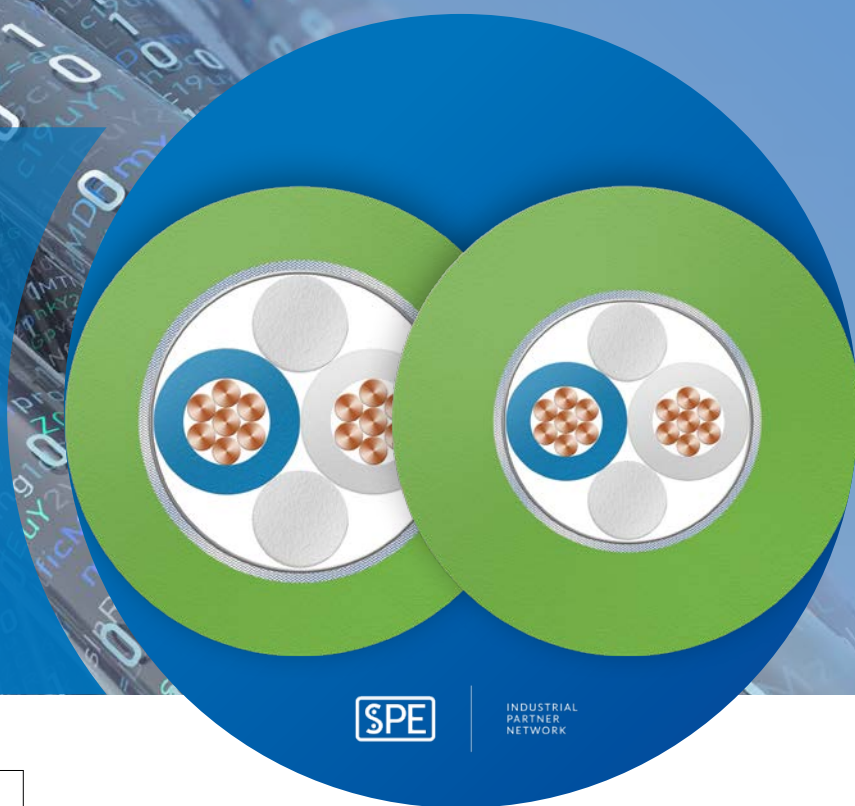

INDUSTRIAL
PARTNER
NETWORK



ADVANTAGES

- Performance up to 1 GBit/s at 600 MHz
- Data transmission up to 40 meters (1 GBit/s) and up to 1000 meters (10 MBit/s)
- Suitable for drag chains and torsional applications
- Oil resistant
- Designed for harsh industrial environments
- Support of PoDL (Power over Data Line)
- Various jacket materials available:
PUR, FRNC, PVC, FEP
- UL and CSA / CPR approved


With the new SPE cable family, BizLink offers a solution for every application. According to the IEC 61156-x standard, the product portfolio comprises trailing, torsion and robotic cables as well as special solutions which combine the single pair Ethernet features with various other elements to form hybrid cables.

The BizLink product range includes the two basic types with 22 AWG and 26 AWG conductors. The 22 AWG solution is characterised by particularly good attenuation. The cable with 26 AWG is suitable for applications with small space.



Sales network Automation & Drives worldwide

Here you can find
our sales network >

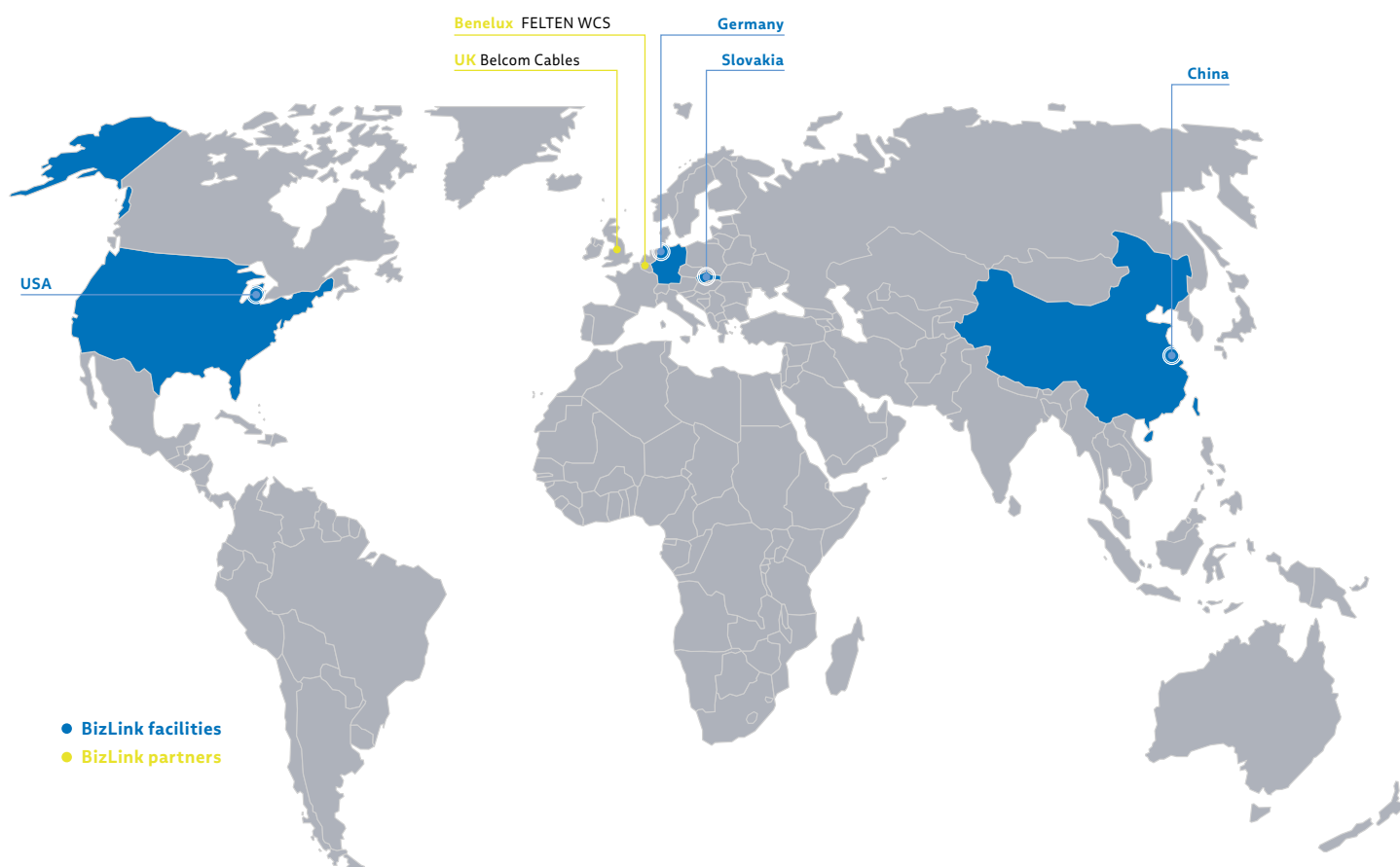

BizLink facilities

BizLink Special Cables Germany GmbH

Eschstrasse 1
26169 Friesoythe, Germany
T +49 4491-291-5010

BizLink Special Cables (Changzhou) Co., Ltd.

No.21, Taihu West Road, Xinbei District,
Changzhou, Jiangsu 213000, China
T +86 21 2213 9061

BizLink Robotic Solutions USA, Inc.

100 Kay Industrial Drive, Lake Orion
Michigan 48359-1831, USA
T +1 248 484-5500

BizLink Industry Slovakia Spol. s.r.o.

Facility Stará Turá

Nám. Dr. A. Schweitzera 194,
916 01 Stará Turá, Slovakia

Facility Jaklovce

Pol'ná 672, 055 61 Jaklovce, Slovakia

Facility Ilava

Trenčianska 401/81, 019 01 Ilava, Slovakia

Sales offices

BizLink Special Cables (Changzhou) Co., Ltd.

Office Shanghai

Room 605, Antna Mansion, No. 107 Zunyi Road,
Changning Area, Shanghai 200051, China
T +86 21 2213 9061