


2.00mm Dual in Line Board to Board Mating Guide

GCT’s value engineered 2.0mm dual in line board to board (B2B) connectors are available for immediate delivery from Digi-Key Electronics. These industry-standard parts are available in multiple pin lengths to suit all options of socket height and entry type.

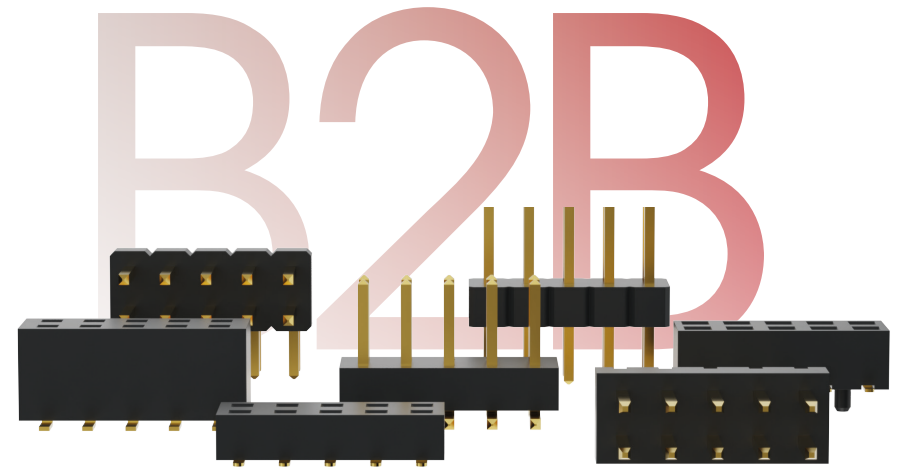

Recommended pin header	Type	Feature	Socket Series		BF121		BF080		BF100	
			Profile		2.20mm		2.80mm		4.30mm	
			Entry type		Top		Bottom		Top	
					Bottom		Top		Bottom	
BF030-xxA-B0-0200-0277-0600-L-B	Vertical SMT	Without locating peg	•		•					
BF030-xxA-B1-0200-0277-0600-L-B	Vertical SMT	With locating peg	•		•					
BF030-xxA-B0-0360-0277-0600-L-B	Vertical SMT	Without locating peg		•			•		•	
BF030-xxA-B1-0360-0277-0600-L-B	Vertical SMT	With locating peg		•			•		•	
BF030-xxA-B0-0600-0277-0600-L-B	Vertical SMT	Without locating peg				•		•		•
BF030-xxA-B1-0600-0277-0600-L-B	Vertical SMT	With locating peg				•		•		•
BF050-xx-A-B-0200-0300-L-G	Vertical TH		•		•					
BF050-xx-A-B-0400-0300-L-G	Vertical TH			•			•		•	
BF050-xx-A-B-0600-0300-L-G	Vertical TH					•		•		•
BF060-xxA-B-0200-0280-0305-L-D	Right angle TH		•		•					
BF060-xxA-B-0400-0280-0305-L-D	Right angle TH			•			•		•	
BF060-xxA-B-0600-0280-0305-L-D	Right angle TH					•		•		•
BF135-xx-A-0200-0700-0400-L-C	Horizontal SMT		•		•					
BF135-xx-A-0400-0700-0400-L-C	Horizontal SMT						•		•	