



Floor and area marking solutions

**Find the right material for your
application needs and budget**

Reliable floor and area marking solutions

Floor marking. It's a critical element in maintaining a safe, compliant and efficient workplace. Whether you're just starting out or taking your floor marking efforts to the next level, Brady offers a variety of good, better and best options to meet your long- and short-term floor and area marking needs. These floor marking options provide:

- High-visibility identification in a variety of colors
- Quick application and easy removal
- Compliance with OSHA and ANSI standards for floor marking

Find the right solution


Get exactly what works for your application, durability needs and budget. Use the chart below and the information on the following pages to pick the right floor marking options for your facility:

	Solution	Key Features	Applications	Learn More
Good Tape				
	B-726 Vinyl Marking Tape	More cost-effective solution for short application period	Temporary marking for 5S/Lean areas, work cells that change and more	Page 10
Better Tape				
	ToughStripe® Floor Marking Tape	Longer application period with more shape and customizability options	Walkways and aisles	Page 5
Best Tape				
	ToughStripe® Max Floor Marking Tape	Highest durability	Higher forklift and industrial vehicle traffic	Page 4
Paint Stencil				
	PaintStripe™ Floor Marking Stencil	Paint stencil for longer, more permanent marking	Permanent work area designation	Page 11

Make every area easily visible

Our wide range of floor marking options can be used in a variety of areas throughout your facility, including:

- Aisle ways and traffic lanes
- Work cell outlines
- Equipment storage areas
- Material storage areas
- QA inspection areas
- Defects/scrap/rework areas
- “Keep clear” zones
- Hazard areas
- **New** – Area marking

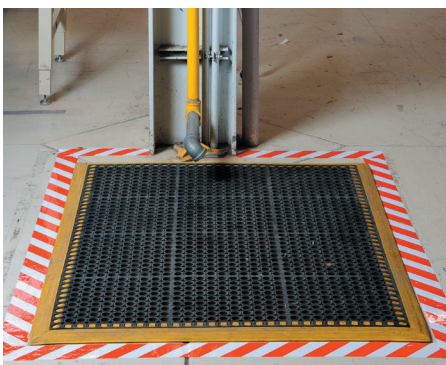

**Best durability
for high-traffic areas**

ToughStripe® Max Floor Marking Tape

The most durable floor tape for identifying high-traffic forklift and industrial vehicle areas

ToughStripe Max offers improved durability in high-traffic areas, where sliding or dragging forces often occur, while maintaining the adhesive capabilities you've come to expect from our ToughStripe floor marking line. With this floor marking tape, you can rely on:

- Greater thickness for resistance to cuts and scrapes in high-traffic areas
- Durability in forklift and industrial vehicle traffic areas
- Aggressive adhesive performance when you need it; easy removal when you don't
- Tapered edges to minimize "pick points" and traffic bumps
- Easy installation with minimal tools



Solid Color ToughStripe Max Tape

Color	2 in. x 100 ft.	3 in. x 100 ft.	4 in. x 100 ft.
Yellow	149629	149636	149643
Black/Yellow striped	149630	149637	149644
Blue	149631	149638	149645
Green	149632	149639	149646

Color	2 in. x 100 ft.	3 in. x 100 ft.	4 in. x 100 ft.
White	149633	149640	149647
Red	149634	149641	149648
Orange	149635	149642	–

▶ ToughStripe Floor Tape Applicator

Get one easy tool for every kind of tape, including:

- B-726 Vinyl Marking Tape (up to 2 in.)
- ToughStripe Floor Marking Tape
- ToughStripe Max Floor Marking Tape

Catalog No.	Description	Quantity
150852	ToughStripe Floor Tape Applicator	1



ToughStripe® Floor Marking Tape

Longer application period with more options for aisle and floor marking

ToughStripe floor marking products are ideal for marking aisles, passageways, storage locations and pointing out important safety equipment and egress paths.

- Rugged polyester with ultra-aggressive adhesive to withstand forklift traffic without tearing or lifting
- Low-profile design minimizes tears and scratches from skids, pallet jacks, etc.
- Easy one-person application with smooth, straight lines
- Stiff polyester with liner prevents tape stretching and reduces wrinkles and wavy, uneven lines
- Lots of variety with customizable colors and messaging, die-cut shapes and print-on-demand options



Solid Color ToughStripe Tape

	2 in. x 100 ft.	3 in. x 100 ft.	4 in. x 100 ft.
Black	104310	104340	104370
White	104311	104341	104371
Red	104313	104343	104373
Green	104315	104345	104375
Blue	104314	104344	104374
Orange	104316	104346	104376
Yellow	104312	104342	104372
Purple	134086	134087	134088
Brown	134089	134090	134091
Grey	134092	134093	134094



Striped ToughStripe Tape

	2 in. x 100 ft.	3 in. x 100 ft.	4 in. x 100 ft.
Orange/Black striped	132433	132434	132435
Yellow/Black striped	104317	104347	104377
White/Black striped	104319	104349	104379
Red/White striped	104318	104348	104378
Red/Yellow striped	132430	132431	132432
Green/White striped	132436	132437	132438
Blue/Yellow striped	132439	132440	132441



Checkered ToughStripe Tape

	2 in. x 100 ft.	3 in. x 100 ft.	4 in. x 100 ft.
Black/White checkered	121913	121914	121915
Red/White checkered	121916	121917	121918



ToughStripe Overlamine Tape

Catalog #	Description	Size
142134	Overlamine	1" x 50'
142136	Overlamine	1.125" x 100'
142135	Overlamine	2" x 50'
142137	Overlamine	2.250" x 100'
142138	Overlamine	3" x 100'
142139	Overlamine	4" x 100'

Die-Cut and Pre-Spaced ToughStripe® Shapes

- Use different shapes, colors and sizes for more effective, durable floor markings
- Die-cut shapes include dashes, dots, arrows, footprints and corner marks
- Dots, arrows and dashes packaged in rolls (not individually)



Dots



	3.5 in. diameter 350/roll
Black	104404
White	104405
Red	104400
Green	104401
Blue	104402
Yellow	104403

Arrows



	2 in. x 5 in. 100/pack	3 in. x 8 in. 100/pack	4 in. x 10 in. 100/pack
Black	104416	104422	104428
White	104417	104423	104429
Red	104412	104418	104424
Green	104413	104419	104425
Blue	104414	104420	104426
Yellow	104415	104421	104427

Corner "L" marks



	2 in. x 5 in. 20/pack	3 in. x 8 in. 20/pack	4 in. x 10 in. 20/pack
Black	104434	104446	104458
White	104435	104447	104459
Red	104430	104442	104454
Green	104431	104443	104455
Blue	104432	104444	104456
Yellow	104433	104445	104457

Footprints



	10 in. x 3.5 in. 5 right and 5 left/pack
Black	104410
White	104411
Red	104406
Green	104407
Blue	104408
Yellow	104409

Center "+" marks



	2 in. x 5 in. 20/pack	3 in. x 8 in. 20/pack	4 in. x 10 in. 20/pack
Black	104470	104476	104482
White	104471	104477	104483
Red	104466	104472	104478
Green	104467	104473	104479
Blue	104468	104474	104480
Yellow	104469	104475	104481

Divider "T" marks



	2 in. x 5 in. 20/pack	3 in. x 8 in. 20/pack	4 in. x 10 in. 20/pack
Black	104440	104452	104464
White	104441	104453	104465
Red	104436	104448	104460
Green	104437	104449	104461
Blue	104438	104450	104462
Yellow	104439	104451	104463

Pre-spaced shapes



	3.5 in. x 100 ft. 55 dots/18" apart	2 in. x 5 in. x 100 ft. 52 arrows/18" apart	2 in. x 8 in. x 100 ft. 46 dashes/18" apart
Black	104525	104554	142178
White	104522	104555	142177
Red	104521	104526	142179
Green	104520	104527	142181
Blue	104524	104528	142180
Yellow	104523	104529	104556

ToughStripe stock legends

	2 in. x 100 ft.	3 in. x 100 ft.	4 in. x 100 ft.
Orange "QA Inspection Area"	121364	121365	121366
Yellow "Caution ESD Area"	121367	121368	121369



Pre-printed legends

Custom legends and colors available

ToughStripe Numbers and Letters

- 6 in. x 8 in. numbers and letters available in a variety of colors
- Numbers and letters come as a pack of 20 sheets
- Punctuation set contains 20 sheets; each sheet contains two periods, one comma, one exclamation point, one question mark, one forward slash, one dash and one ampersand (&)



Legend	Black	White	Red	Green	Blue	Yellow
A	121691	121692	121693	121694	121695	121696
B	121697	121698	121699	121700	121701	121702
C	121703	121704	121705	121706	121707	121708
D	121709	121710	121711	121712	121713	121714
E	121715	121716	121717	121718	121719	121720
F	121721	121722	121723	121724	121725	121726
G	121727	121728	121729	121730	121731	121732
H	121733	121734	121735	121736	121737	121738
I	121739	121740	121741	121742	121743	121744
J	121745	121746	121747	121748	121749	121750
K	121751	121752	121753	121754	121755	121756
L	121757	121758	121759	121760	121761	121762
M	121763	121764	121765	121766	121767	121768
N	121769	121770	121771	121772	121773	121774
O	121775	121776	121777	121778	121779	121780
P	121781	121782	121783	121784	121785	121786
Q	121787	121788	121789	121790	121791	121792
R	121793	121794	121795	121796	121797	121798

Legend	Black	White	Red	Green	Blue	Yellow
S	121799	121800	121801	121802	121803	121804
T	121805	121806	121807	121808	121809	121810
U	121811	121812	121813	121814	121815	121816
V	121817	121818	121819	121820	121821	121822
W	121823	121824	121825	121826	121827	121828
X	121829	121830	121831	121832	121833	121834
Y	121835	121836	121837	121838	121839	121840
Z	121841	121842	121843	121844	121845	121846
0	121847	121848	121849	121850	121851	121852
1	121853	121854	121855	121856	121857	121858
2	121859	121860	121861	121862	121863	121864
3	121865	121866	121867	121868	121869	121870
4	121871	121872	121873	121874	121875	121876
5	121877	121878	121879	121880	121881	121882
6	121883	121884	121885	121886	121887	121888
7	121889	121890	121891	121892	121893	121894
8	121895	121896	121897	121898	121899	121900
9	121901	121902	121903	121904	121905	121906
Punctuation set	121907	121908	121909	121910	121911	121912

B-483 Print-On-Demand ToughStripe Tape with Overlaminate

- Printable label rolls can be used to create custom floor labels for identifying storage locations and providing visual instructions on the shop floor
- Easy 3-step process: Print desired label from a select Brady printer, position label on floor and apply included B-634 polyester overlaminate for print protection



ToughStripe Tape for S3100, BBP®35 and BBP®37 Printers

Fits Printer(s)	Color	1.125 in. x 100 ft.	2.25 in. x 100 ft.	3 in. x 100 ft.	4 in. x 100 ft. ✂ For BBP37 XY-Cutter	Rec. Ribbon
S3100, BBP35, BBP37	White	B30C-1125-483WT-KT	B30C-2250-483WT-KT	B30C-3000-483WT-KT	B30C-4000-483WT-KT	B30-R6000
S3100, BBP35, BBP37	Yellow	B30C-1125-483YL-KT	B30C-2250-483YL-KT	B30C-3000-483YL-KT	B30C-4000-483YL-KT	B30-R6000
S3100, BBP35, BBP37	Orange	B30C-1125-483OR-KT	B30C-2250-483OR-KT	–	B30C-4000-483OR-KT	B30-R6000
S3100, BBP35, BBP37	Red	B30C-1125-483RD-KT	B30C-2250-483RD-KT	–	B30C-4000-483RD-KT	B30-R4400-WT
S3100, BBP35, BBP37	Green	B30C-1125-483GN-KT	B30C-2250-483GN-KT	–	B30C-4000-483GN-KT	B30-R4400-WT
S3100, BBP35, BBP37	Blue	B30C-1125-483BL-KT	B30C-2250-483BL-KT	–	B30C-4000-483BL-KT	B30-R4400-WT
S3100, BBP35, BBP37	Black	B30C-1125-483BK-KT	B30C-2250-483BK-KT	–	B30C-4000-483BK-KT	B30-R4400-WT

ToughStripe Tape for BMP®71 Printer

Fits Printer	Color	1 in. x 50 ft.	2 in. x 50 ft.	Rec. Ribbon
BMP71	White	M71-1000-483-WT-KT	M71-2000-483-WT-KT	M71-R6000
BMP71	Yellow	M71-1000-483-YL-KT	M71-2000-483-YL-KT	M71-R6000
BMP71	Orange	M71-1000-483-OR-KT	M71-2000-483-OR-KT	M71-R6000
BMP71	Red	M71-1000-483-RD-KT	M71-2000-483-RD-KT	M71-R4400-WT
BMP71	Green	M71-1000-483-GN-KT	M71-2000-483-GN-KT	M71-R4400-WT
BMP71	Blue	M71-1000-483-BL-KT	M71-2000-483-BL-KT	M71-R4400-WT
BMP71	Black	M71-1000-483-BK-KT	M71-2000-483-BK-KT	M71-R4400-WT

B-534 Floor Marking Signs with Anti-Slip Tread



Arrow Symbol
104489 - 17 in. dia.



Emergency Exit
104495 - 17 in. dia.



Emergency Stairs
104496 - 17 in. dia.



Exit Arrow
104490 - 17 in. dia.



Fire Extinguisher
104492 - 17 in. dia.



Fire Alarm
104493 - 17 in. dia.



Fire Hose
104494 - 17 in. dia.



Pedestrian Traffic Only
104509 - 17 in. dia.



Watch Out For Fork Lift
104501 - 17 in. dia.



Warning Forklift Traffic
104512 - 17 in. dia.



Production Area
104513 - 17 in. dia.



First Aid w/Arrow
104486 - 17 in. dia.



Safety Shower
104487 - 17 in. dia.



Eye Wash
104507 - 17 in. dia.



Stop
104511 - 17 in. dia.



Keep Aisles Clear
104508 - 17 in. dia.



Radiation Area
104488 - 14 in. x 18 in.



First Aid
104491 - 14 in. x 18 in.



Do Not Enter
104497 - 14 in. x 18 in.



Chemical Storage
104498 - 14 in. x 18 in.



Watch Your Step
104499 - 14 in. x 18 in.



No Smoking
104500 - 14 in. x 18 in.



Ear Protection Area
104502 - 14 in. x 18 in.



Eye Protection Area
104503 - 14 in. x 18 in.



Hard Hat Area
104504 - 14 in. x 18 in.



Safety Goggles Required
104505 - 14 in. x 18 in.



Biohazard
104506 - 14 in. x 18 in.



Safety Glasses Required
104510 - 14 in. x 18 in.

Premium Lean / 5S Kits with ToughStripe® Floor Marking Tape

Everything you need to make your facility 5S/Lean, enhancing workplace organization and efficiency.



Premium Lean / 5S Marking Kit includes:

ToughStripe floor marking tape

- 4 rolls of 2 in. ToughStripe floor tape (1 yellow, 1 red, 1 blue, 1 green)
- 4 packages of 2 in. L-shaped corner marks (1 yellow, 1 red, 1 blue, 1 green)

Toolboard / workbench marking tapes

- 4 rolls of 12 in. shadow vinyl (1 black, 1 red, 1 blue, 1 green)
- 4 rolls of ½ in. border tape (1 black, 1 red, 1 blue, 1 green)
- 4 rolls of ½ in. L-shaped corner marks (1 black, 1 red, 1 blue, 1 green)

Premium Lean / 5S Kit with BMP®71 Label Printer includes:

- All contents of Premium Lean / 5S Marking Kit above, plus:
- BMP71 Printer with hard carrying case and charger/AC power adaptor
- 3 white vinyl tape cartridges (1/2 in., 1 in., 2 in.)
- 1 yellow vinyl tape cartridge (2 in.)
- 2 ribbon cartridges (1 black, 1 red)


Catalog #	Description
142109	Premium Lean / 5S Kit
142111	Premium Lean / 5S Kit with BMP71 Label Printer

B-726 Vinyl Floor Marking Tape

Cost-effective floor marking solution for short-term application

Brady's B-726 abrasion-resistant vinyl tape makes your facility safer, more visual and more efficient by adding colorful visual indicators to aisles and passageways, at a lower price.

- Pressure-sensitive rubber-based adhesive sticks tightly to virtually any clean, dry surface
- Ideal for temporarily marking aisles, passageways and storage locations and identifying equipment and egress paths

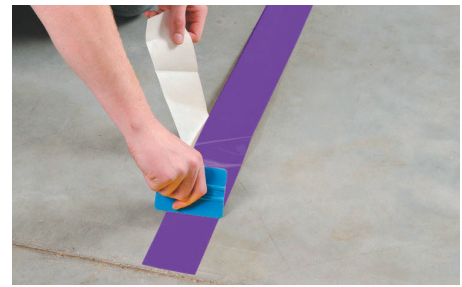

Solid Color Tape

Color	2 in. x 108 ft.	3 in. x 108 ft.	4 in. x 108 ft.
Yellow	58200	58250	102838
Red	58201	58251	102836
Green	58202	58252	102834
White	58203	58253	102837
Blue	58220	58221	102833
Black	58222	58223	102839
Orange	102825	102829	102835
Brown	102828	102832	102840
Purple	102827	102831	-
Grey	102826	102830	-

PaintStripe™ Floor Marking Stencil

Quickly apply clean, straight lines for permanent identification

PaintStripe floor marking stencils are ideal when paint is preferred, such as in areas with aggressive or abrasive traffic, or facilities that are unable to use aisle marking tapes due to wet floors, washdown conditions, floor-cleaning protocols or chemical exposures.

- Continuous and dashed-line formats, with line widths of 2, 3 or 4 in.
- Two adhesive types to securely mask edges and provide professional, permanent floor marking for industrial floors
- Printed cut-lines and a repeating 12 in. ruler facilitate accurate length measurement and rapid alignment of 90° corners



Lower adhesion (B-518) Ideal for clean, polished floors

Catalog #	Description	Size	Qty
148820	Smooth floors	2 in. Line	100 ft. roll
148808	Smooth floors	2 in. Line	500 ft. roll
148815	Smooth floors	2 in. x 8 in. Dash	100 ft. roll
148823	Smooth floors	2 in. x 8 in. Dash	500 ft. roll
148814	Smooth floors	3 in. Line	100 ft. roll
148819	Smooth floors	3 in. Line	500 ft. roll
148806	Smooth floors	4 in. Line	100 ft. roll
148816	Smooth floors	4 in. Line	500 ft. roll

Higher adhesion (B-519) Ideal for dull or worn surfaces

Catalog #	Description	Size	Qty
148813	Rough floors	2 in. Line	100 ft. roll
148822	Rough floors	2 in. Line	500 ft. roll
148812	Rough floors	2 in. x 8 in. Dash	100 ft. roll
148818	Rough floors	2 in. x 8 in. Dash	500 ft. roll
148809	Rough floors	3 in. Line	100 ft. roll
148821	Rough floors	3 in. Line	500 ft. roll
148810	Rough floors	4 in. Line	100 ft. roll
148807	Rough floors	4 in. Line	500 ft. roll

When planning projects, be sure to test the stencil and paint combination on the intended floor surface.

We identify and protect premises, products and people.

For more information or to learn more about our innovative products, visit BradyID.com or call 1-888-272-3946.



Y4670477 MS4670477

© 2019 Brady Worldwide Inc. ALL RIGHTS RESERVED

USA
Customer Service: 1-888-272-3946
Inside Sales: 1-888-311-0775
BradyID.com

Canada
Customer Service: 1-800-263-6179
BradyCanada.ca

Mexico
Customer Service: 1-800-262-7777
Inside Sales: 1-800-262-7777 ext 177
BradyLatinAmerica.com

